

Pre-Crimped Leads >

Molex's range of pre-crimped leads offers a simple, cost-effective solution for prototyping, pre-production and mass production requirements. These leads are offered in female-to-female and male-to-male configurations in lengths of 75.00 to 600.00mm.



C-Grid III




CLIK-Mate



DuraClik



iGrid

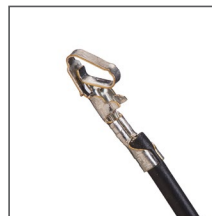

KK



KK Plus



Mega-Fit



MicroClasp



Micro-Fit 3.0



Micro-Fit Plus




Micro-Lock Plus




Micro-One



Milli-Grid

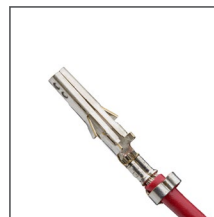

Mini-Fit

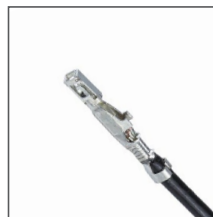

Mini-Fit Max




Mini-Fit Sigma




Mini-Fit Sr.




Mini-Lock

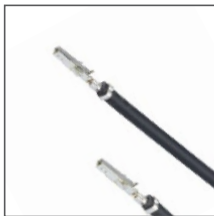

Mini-Fit Versa Color

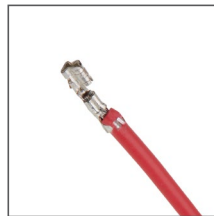

Mini-SPOX

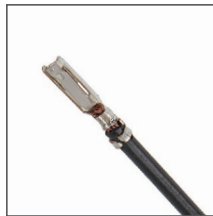

Mizu-P25



MLX



MOX



MX150




Nano-Fit



OneBlade



PicoBlade

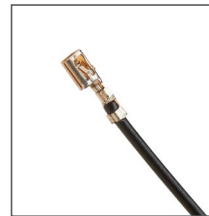

Pico-Clasp




Pico-EZmate




Pico-Lock



Pico-SPOX

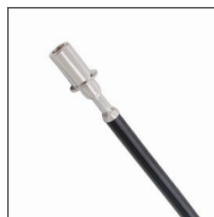

PowerWize

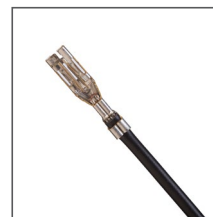

Sabre



Sherlock



SL



Solderless Ring

Pre-Crimped Leads



Squaba



Stac64



Standard .062"



Standard .093"



Ultra-Fit



Zero-Hachi



CP



DuraClik



CP4.5



CEM5

Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
C-Grid	79758	150, 300	Female	Female	22	UL 1061
CLIK-Mate	79758, 215710, 215711	75, 150, 225, 300, 450	Female, Male	Female, Male	24, 26, 28	UL 1061, UL 10002
CP Term	227903 221951 228038	150, 300, 450	Female	Female Strip	0.75mm ² 0.50mm ²	FLRYW, FLRYW125-B
CP4.5 Term	227107 227108	150, 300, 450	Female	Female Strip	16, 18	FLYW
DuraClik	227022 227023	150, 300, 450	Female	Female Strip	22, 24	ENDURA
iGrid	217490, 217491	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 10002
KK	79758	150, 300	Female, Male	Female, Male	22, 24	UL 1061, UL 1007
KK Plus	79758, 217510, 217511	75, 150, 225, 300, 450	Female	Female	18, 22, 24, 26	UL 1015, UL 1569
Mega-Fit	79758	150, 300	Female	Female	16, 12	UL 1015
Micro-Clasp	79758	150, 300	Female	Female	24	UL 1007
Micro-Fit 3.0	79758, 214760, 214761, 214762, 214763	150, 300, 600	Female, Male	Female, Male	18, 20	UL 1061, UL 10002
Micro-Fit Plus	36769	300	Female, Male	Strip and Tin	16, 20, 24	UL 1061 (16AWG) UL 11028 (20AWG, 24AWG)

Pre-Crimped Leads



Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
Micro-Lock Plus	79758, 217500, 27501	75, 15, 225, 300, 450	Female	Female, Strip	22, 24, 26	UL 1061, UL 10002
MicroFit+ CEM5	228369, 228370, 228431, 228432	150, 300, 450	Female	Female, Strip	16, 28	UL 1061
Micro-One	219654	Female	Female	Female	22	UL 1569
	219655			Female, Strip	22, 24, 26	
Mini-Fit Max	224087, 224088	16, 28	Female	Female	2.00	UL1569
Mini-Fit Sr.	217480, 217481, 217482, 217483	UL 1061	Female, Male	Female, Male	8, 10, 12	UL 10669
Mini-Fit Versa Color	226197	150, 300, 450	Female, Male	Female, Male, Strip and Tin	18, 20	UL 1015
Mini-Lock	79758	150, 300	Female	Female	22	UL 1061
Mini-Spox 2.5	219676, 219677	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 1569
Mizu-P25	217840, 217841, 217842, 217843, 217520, 217521, 217522, 217523	75, 150, 225, 300, 450	Female, Male	Female, Male	20, 22	UL10002, FLRY-B
MLX	79758	150, 300	Female, Male	Female, Male	18	UL 1015
MOX	226208	150.00, 300.00, 450.00	Female	Female, Strip	20, 22	SAE1128-TXL
MX150	226208	150, 225, 300, 450, 600	Female, Male	Female, Male	14, 16, 18	TXL
Nano-Fit	79758	150, 300	Female	Female	20	UL 1061
OneBlade	79758	150, 300, 450	Female	Female, Strip and Tin	28, 30	UL 10125
PicoBlade	79758, 214902, 214921, 214922, 214923	75, 150, 225, 300, 450	Female, Male	Female, Male and Strip	26, 28	UL 1061
Pico-Clasp	79758	150, 300	Female	Female	28	UL 1571
Pico-EZmate	79758	300	Female	Female	28	UL 1516

Pre-Crimped Leads



Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
Pico-Lock	79758	150, 300	Female	Female	24, 30	UL 1061, UL 1571
Pico-SPOX	79758	150, 300	Female	Female	24	UL 1061
PowerWize	221960	600	Female	Female	2	UL 10198
			Female	Strip		
Sabre	79758	150, 300	Female, Male	Female, Male	16	UL 1015
Sherlock	79758	150, 300	Female	Female	26	UL 1061
Squba	217790, 217791, 217792, 217793, 219676, 219677	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 10002, UL 1569
Stac64	224451, 224452, 224572	150, 300, 450	Female	Female, Strip	18, 20	FLRYW
Standard .062"	79758	150, 300	Female, Male	Female, Male	22	UL 1015
Standard .093"	79758	150, 300	Female, Male	Female, Male	18	UL 1015
Ultra-Fit	79758, 217470, 217471	75, 150, 225, 300, 450	Female	Female	16, 18, 20	UL 1061, UL 11028
Zero-Hachi	219672, 219673	150, 300, 450	Female	Female, Strip and Tin	28, 30	10064

Product Family	Series Number	Length (mm)	Stud Size	Wire Termination	Wire Size (AWG)	Wire/Cable Type
Solderless Ring Terminal	217851	150	10 (M5)	Blunt cut	16 AWG	UL 1015
		300				
		600				

www.molex.com/link/precrimped.html