


SlimStack Board-to-Board Signal Connectors

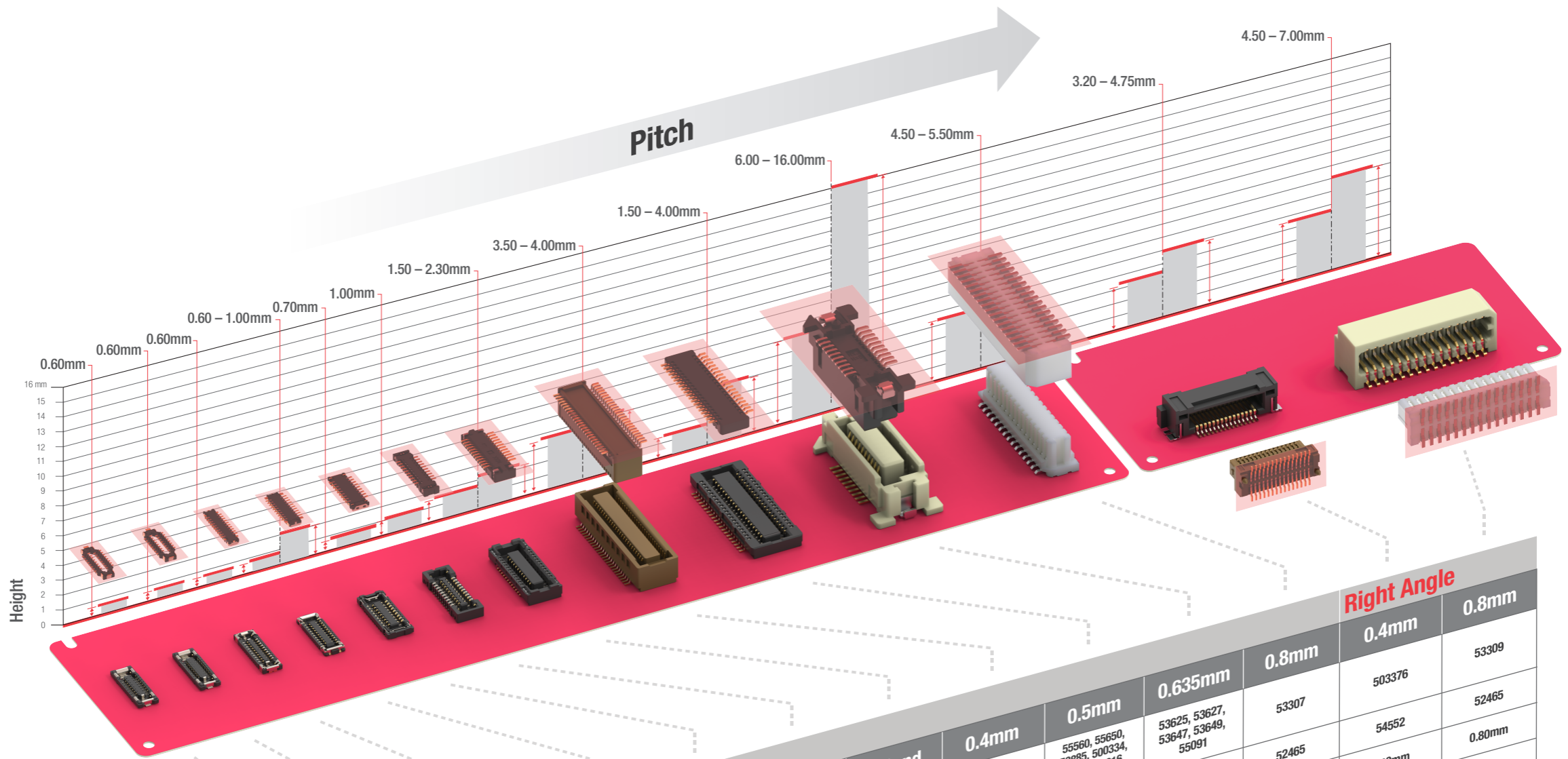

Product	Vertical				Right Angle								
	Quad Row Gen 1	Quad Row Gen 2	ACB6+	SSB RP	HRF 7S	T10	J-Bend	0.4mm	0.5mm	0.635mm	0.8mm	0.4mm	0.8mm
Plug Series	203390	217717	216701	505070, 505274, 505417	503552	502430	55909, 501745	501017, 55526	55560, 55650, 53885, 500334, 53748, 53916, 501920	53625, 53627, 53647, 53649, 55091	53307	503376	53309
Rec Series	203389	217716	216700	505066, 505270, 505413	503548	502426	51338, 500913	54684	54722, 54363, 54102, 52991	209168, 52901, 52885	52465	54552	52465
Pitch	0.175mm	0.175mm	0.35mm	0.35mm	0.40mm	0.40mm	0.40mm	0.40mm	0.40mm, 0.50mm, 0.635mm	0.80mm	0.80mm	0.40mm	0.80mm
Circuit	32, 36	20, 64	10 to 60	6 to 60	6, 10, 12, 14, 16, 18	8 to 90	10 to 100	24, 50, 60, 80, 100, 120	16 to 80	20 to 240	10 to 40	24, 50, 60, 80, 100, 120	10 to 36
Mating Height	0.60mm	0.60mm	0.60mm	0.60mm/1.00mm	0.70mm	1.00mm	1.50mm/2.30mm	3.50mm/4.00mm	1.50mm/4.00mm	6.00mm/16.00mm	4.50mm/5.50mm	3.20mm/4.75mm	4.50mm-7.00mm
Mating Width	2.00mm	2.00mm	1.90mm	2.00mm	2.60mm	2.60mm	3.40mm/4.20mm	3.70mm	5.30mm/6.00mm	6.40mm	5.10mm/7.20mm	3.70mm	4.70mm/7.20mm