


COEUR-Enabled High-Voltage, High-Current Connectors

PowerWize High-Voltage High-Current Connectors

Wire-to-Board
Wire-to-Busbar

Current Rating:
6.00mm: 120.0A
8.00mm: 180.0A

Voltage Rating (max.): 1,000V
6.00mm: 1,000V
8.00mm: 1,000V

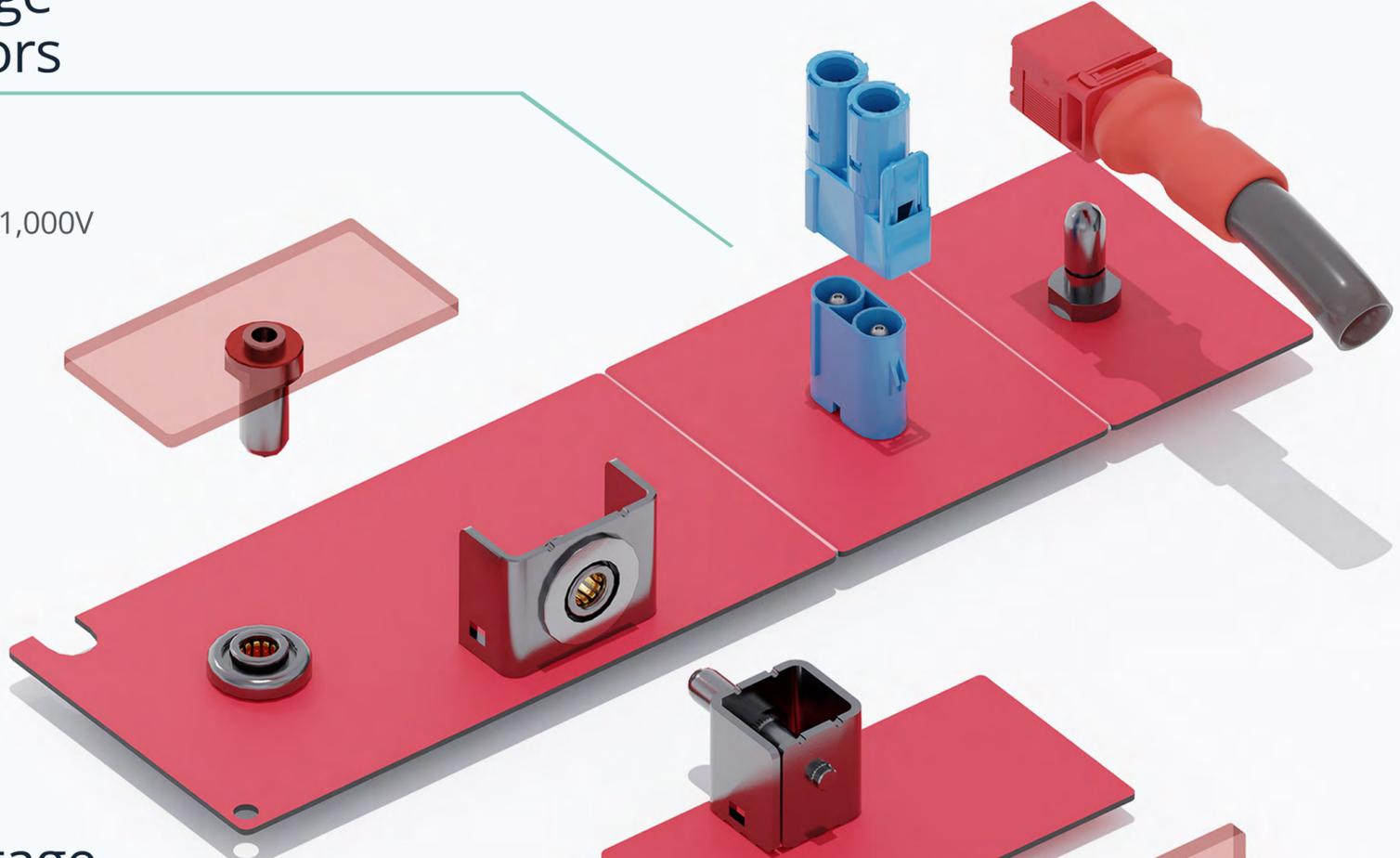

SW1 High-Voltage High-Current Connectors

Wire-to-Board
Wire-to-Busbar

Current Rating:
6.00mm: 120.0A
8.00mm: 185.0A
11.00mm: 300.0A

Voltage Rating (max.): 1,000V

Sentrality High-Voltage High-Current Connectors

Board-to-Board
Board-to-Busbar
Busbar-to-Busbar

Current Rating(max.):
3.4mm: 75.0A
6.00mm: 140.0A
8.00mm: 200.0A
11.00mm: 350.0A

Voltage Rating (max.): 1,000V

